

Price List Addendum

EFFECTIVE May 1, 2020




PL2020-GEN-ADD6


Grooved IPS Pipe Fittings

Schedule 80 3D Long Radius Cast Ductile Iron Elbows

Refer to publication 07.12

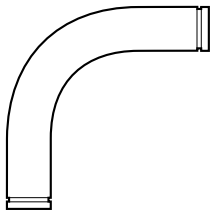

No. 100-3D
90° Long Radius Elbow

 


No. 110-3D
45° Long Radius Elbow


SCHEDULE 80 3D LONG RADIUS CAST DUCTILE IRON ELBOWS – 90° ELBOW AND 45° ELBOW

Nom. Size	90° Elbow No. 100-3D			45° Elbow No. 110-3D		
	Approx. Wgt. Ea. lb	Price Each		Approx. Wgt. Ea. lb	Price Each	
		Painted	Galv.		Painted	Galv.
6	86.3	\$1229.50	\$1414.00	56.2	\$882.00	\$1014.50
8	154.7	2935.50	3375.50	84.0	1533.00	1763.00

 Note: For use with Victaulic couplings only. Prepare pipe ends in accordance with Publication 25.02.



No. 12-3D
22½° Long Radius Elbow

 

No. 13-3D
11¼° Long Radius Elbow



No. 21-3D
6° Long Radius Elbow

SCHEDULE 80 3D LONG RADIUS CAST DUCTILE IRON ELBOWS – 22½° ELBOW, 11¼° ELBOW, AND 6° ELBOW

Nom. Size	22½° Elbow No. 12-3D			11¼° Elbow No. 13-3D			6° Elbow No. 21-3D		
	Approx. Wgt. Ea. lb	Price Each		Approx. Wgt. Ea. lb	Price Each		Approx. Wgt. Ea. lb	Price Each	
		Painted	Galv.		Painted	Galv.		Painted	Galv.
6	41.4	\$844.00	\$971.00	35.6	\$844.00	\$971.00	21.7	\$844.00	\$971.00
8	75.0	1371.50	1577.50	66.1	1371.50	1577.50	31.0	1371.50	1577.50

Note: For use with Victaulic couplings only. Prepare pipe ends in accordance with Publication 25.02.

TERMS AND CONDITIONS OF SALE

Victaulic published Terms and Conditions of Sale listed in General Price List will apply. Prices, Designs and Conditions of Sale are subject to change without notice.

P.O. Box 31, Easton, PA 18044-0031 • 4901 Kesslersville Road, Easton, PA 18040 • 1-800-PICK-VIC (1-800-742-5842) • 1-610-250-8817 (fax) • pickvic@victaulic.com

